


Veículo de condutor único TRONIC

Mobile and flexible solutions to unwind, store and transport single core coils and spools.

Info

TRONIC products are optimized for LAPP single core coils H05V-K and H07V-K (Maxi ring) as well as for LAPP single core spools.

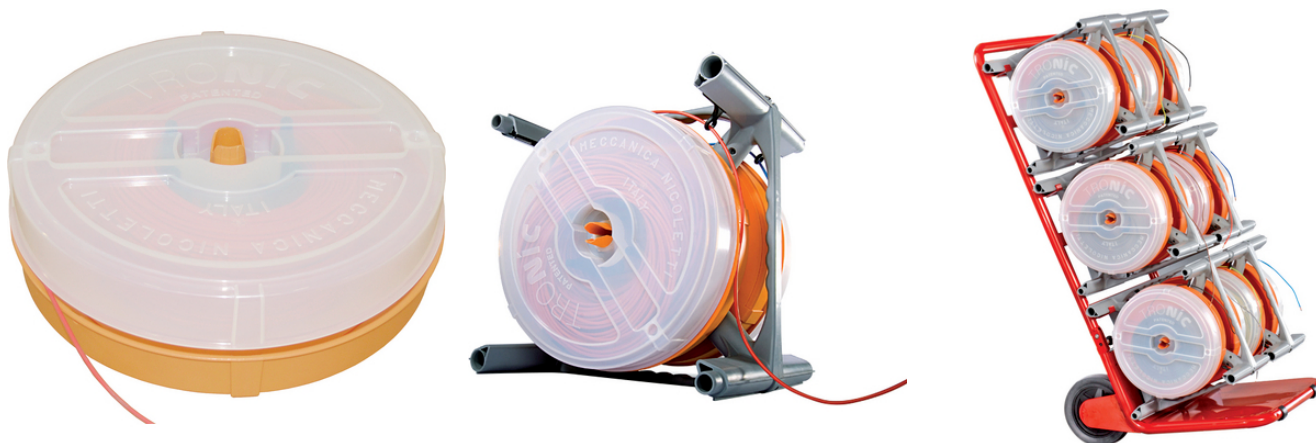

Vantagens

Easy and mobile handling and storage of single core Coils and spools and increases occupational safety and tidy workplaces
Direct bundling of single cores at the operation site leads to efficient assembly
User-friendly solution because of short setup times due to an easy refill
No twisting / kinking through horizontal pull
Mounting of barcodes enables to use kanban solutions , furthermore FLEXIMARK® markings are also possible

Âmbitos de aplicação

Transporting, storing and unwinding of single core coils and spools
Overcoming stairs and other barriers with the Climber version
All in one compact mobile storage and unwinding solution for the operational site

Características do produto

TRONIC module consists of 2 TRONIC boxes mounted on a holder
TRONIC Single core-cart S12:
Capacity for 12 to 18 single core spools (depending on spools width)
Cart with tool holder
TRONIC Module single core cart Climber with stair climber and optionally a tray for tools (article no.: 85001640)

Dados técnicos

Dimensões:

Fits for cable rings:
Cable outer diameter: max. 10 mm
Coil Diameter: max. 295 mm
Inner diameter: 80-180 mm
Height: max. 80 mm

Dados gerais:

Carga máx. por TRONIC: 7 kg
Max. loading TRONIC Single core-cart S12:
1. Level: 60 kg
2. Level: 40 kg
3. Level: 30 kg

Material:

Painted steel

Última atualização (23.04.2024)

©2024 Lapp Group - all rights reserved.

Gestão de Produtos <http://lappbrasil.lappgroup.com>

Você pode encontrar os dados técnicos atuais na folha de dados correspondente.

PN 0456 / 02_03.16

Veículo de condutor único TRONIC

Observação

TRONIC é uma marca da empresa Meccanica Nicoletti S.R.L.




As imagens e gráficos demonstradas não são reprodução fiel do produto, são meramente ilustrativos

Os preços são preços líquidos sem IVA e sobretaxas. Venda apenas para clientes empresariais.

Veículo de condutor único TRONIC

Código do Produto	Descrição do Produto	Contém	Capacidade dos anéis	Dimensão em mm	Peso kg
85001632	TRONIC Box	-	1	D=310.0, H=103.0	0,7
85001624	Veículo de condutor único TRONIC 12	12 TRONIC	12	L=670.0, W=610.0, H=950.0	19
85001629	Veículo de condutor único TRONIC 48	48 TRONIC	48	L=865.0, W=770.0, H=1460.0	106
85001625	Módulo TRONIC	2 TRONIC	2	L=335.0, W=335.0, H=280.0	2,6
85001621	Veículo de condutor único do módulo TRONIC 6x2	6 TRONIC Module	12	L=610.0, W=600.0, H=1270.0	29
85001622	Veículo de condutor único do módulo TRONIC 18x2	18 TRONIC Module	36	L=840.0, W=820.0, H=1400.0	93
85001639	TRONIC Module single core cart Climber	6 TRONIC Module	12	L=710.0, W=680.0, H=1360.0	40
85001628	TRONIC Single core-cart S12	-	18	L=620.0, W=590.0, H=1160.0	20
Acessórios					
85001637	TRONIC cover	1 transparentní víko	-	-	-

Veículo de condutor único TRONIC

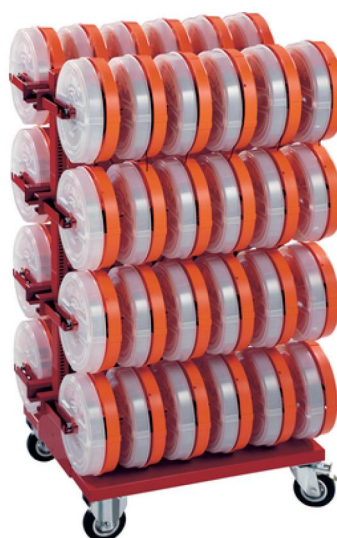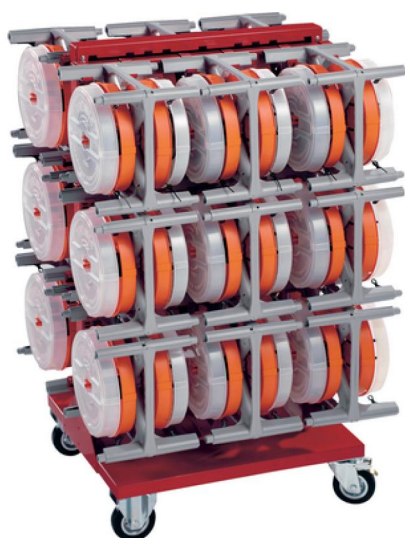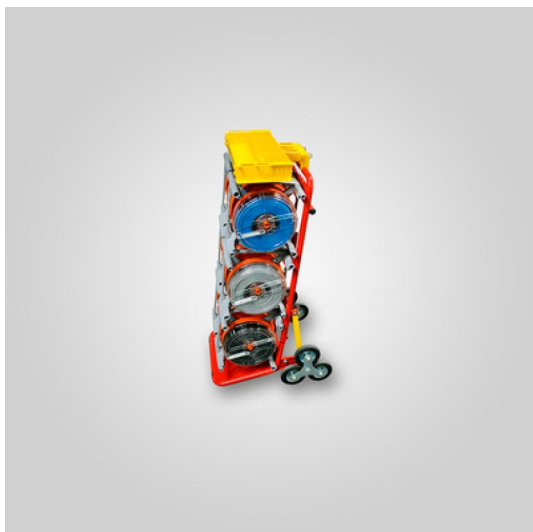

Última atualização (23.04.2024)

©2024 Lapp Group - all rights reserved.

Gestão de Produtos <http://lappbrasil.lappgroup.com>

Você pode encontrar os dados técnicos atuais na folha de dados correspondente.

PN 0456 / 02_03.16