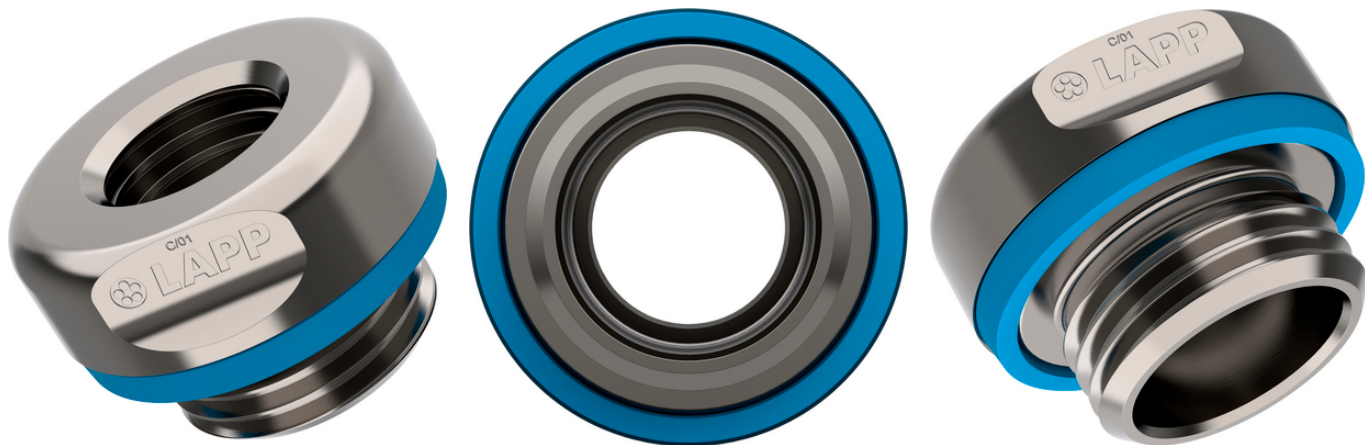


SKINDICHT® R-M HYGIENIC

-  Alimento e Bebidas
-  Engenharia de máquinas e instalações
-  Óleo e gás
-  Boa resistência química
-  Resistente ao calor
-  Robusto
-  Resistente a temperatura
-  A prova d'água

Vantagens

Hygienic design with smooth surfaces and contours without corners and edges prevents residues such as liquids and micro-organisms from accumulating and posing a risk of contamination for food processing machinery. This facilitates simple, frequent and safe product cleaning.

Corrects the size difference between the connection thread of a cable gland and the threaded hole in an enclosure.

Provides flexibility in the selection of a cable gland, as the selection is independent to the threaded hole of the enclosure.

Multiple food and beverage certifications for Europe and North America.

Tested resistance to ECOLAB® disinfectants and cleaning agents.

SKINDICHT® R-M HYGIENIC

Âmbitos de aplicação

For use with metric SKINTOP® HYGIENIC/SKINTOP® INOX M cable glands whose connecting thread is smaller than the existing threaded hole.

Especially for hygiene-critical areas of the food industry, where the product needs to be installed in the product zone or in the direct food production environment.

Also suitable for use in hygiene-critical areas of the pharmaceutical and chemical industry.

Withstands high chemical and mechanical stress.

Referências às normas / Aprovações

FKM-sealing compliant acc. FDA 21 CFR 177.2600

Projeto do produto

Rosca de conexão métrica de acordo com DIN EN 60423

Base para especificações técnicas DIN IEC 62444

Dados técnicos

Classificação ETIM 5:

ETIM 5.0 Class-ID: EC000441

Descrição de classe ETIM 5.0: Prensa-cabo rosqueado

Classificação ETIM 6:

ID da classe ETIM 6.0: EC000441

Descrição da classe ETIM 6.0: Prensa-cabos

Cor de fornecimento:

Sealing: RAL 5015 (sky blue)

Material:

Corpo: Aço inoxidável - V4A (1.4404 / 316L) Vedação: FKM

Faixa de temperatura:

-20°C up to 220°C

Observação

As imagens e gráficos demonstradas não são reprodução fiel do produto, são meramente ilustrativos

Os preços são preços líquidos sem IVA e sobretaxas. Venda apenas para clientes empresariais.



SKINDICHT® R-M HYGIENIC

Código do Produto	Rosca externa M1	Rosca interna M2	SW wrench size mm	Comprimento total C mm	Thread length D mm	Ø externo mm	Peça/emb.
52103596	16 x 1,5	12 x 1,5	20	15.5	7	22.8	5
52103597	20 x 1,5	12 x 1,5	24	17.5	8	26.8	5
52103598	20 x 1,5	16 x 1,5	24	17.0	8	26.8	5
52103599	25 x 1,5	16 x 1,5	29	18.0	8	31.8	5
52103600	25 x 1,5	20 x 1,5	29	18.0	8	31.8	5
52103601	32 x 1,5	20 x 1,5	36	21.0	9	39.6	5
52103602	32 x 1,5	25 x 1,5	36	21.0	9	39.6	5